


MINI-SPLIT WIRE 300 VOLT SHIELDED

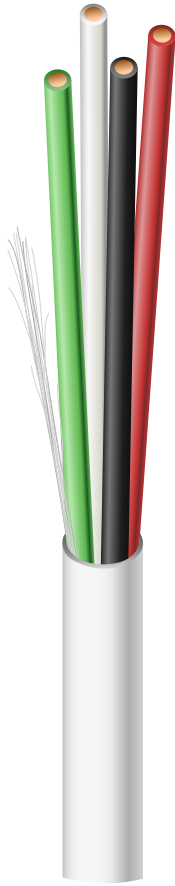

APPLICATIONS Suitable for use as follows:

- Mini-Split Wire is a class 3 power-limited circuit cable used with HVAC Mini-Split systems
- Also can be used in security and audio applications

STANDARDS & REFERENCES

- 300 voltage rating per NEC® Article 725
- Riser Rated
- UL listed as per UL 13
- Meets UL 1581 Vertical Tray Flame Test
- Type CL3R
- RoHS Compliant

CONSTRUCTION

- Stranded copper conductors with 10 mils of PVC insulation
- The overall jacket is heat, moisture and sunlight resistant PVC
- Overall aluminium mylar shield with 24 AWG tinned copper drain wire

300 Volt

CL3R

PVC Jacket

Rip Cord



greenSpec[®]
RoHS Compliant
2002/95/EC



HVAC

WEIGHTS, MEASUREMENTS, AND PACKAGING

SIZE (AWG) / NUMBER OF CONDUCTORS	CONDUCTOR COLORS	JACKET THICKNESS NOM. (mils) / COLOR	APPROX. O.D. (mils)	APPROX. NET WT. (lbs/1000 ft)
18/2	Black, Red	15/Gray	159	18
18/4	Black, Red, Green, White	15/Gray	278	33
16/2	Black, Red	15/Green	183	25
16/4	Black, Red, Green, White	15/Green	326	47
14/4	Black, Red, Green, White	15/White	379	69

MINI-SPLIT WIRE 300 VOLT SHIELDED